


Cable DisplayPort 1.2 male > DisplayPort male 4K 5 m

Description

This cable enables you to connect DisplayPort devices e.g. a monitor to your PC. The DisplayPort is standardized universal connecting standard by VESA for the transfer of video and audiosignal. It can be applied for monitors, TV to computer, DVD-player and similar devices.

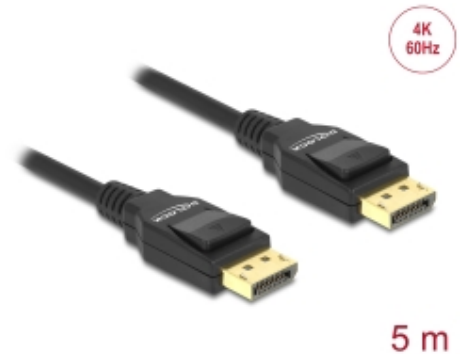

Item no. 82425

EAN: 4043619824250

Country of origin: China

Package: Poly bag

Technical details

- Connector:
 - DisplayPort 20 pin male >
 - DisplayPort 20 pin male
- DisplayPort 1.2 specification
- 20 pin is connected (supports 3.3 V)
- Cable gauge:
 - 30 AWG data line
 - 28 AWG power line
- Cable diameter: ca. 6 mm
- Twisted-pair cabling
- Copper conductor
- Gold-plated connector
- Triple shielded cable
- Transfer of audio and video signals
- Data transfer rate up to 21.6 Gb/s
- Resolution up to 3840 x 2160 @ 60 Hz (depending on the system and the connected hardware)
- Colour: black
- Length incl. connector: ca. 5 m

System requirements

- A free DisplayPort interface

Package content

- DisplayPort cable

Images



General

Specification:	DisplayPort 1.2
Style:	both sides identical

Interface

Connector 1:	1 x DisplayPort male
Connector 2:	1 x DisplayPort male

Technical characteristics

Data transfer rate:	21.6 Gbps
Maximum screen resolution:	3840 x 2160 @ 60 Hz

Physical characteristics

Housing material:	PVC
Connector finishing:	gold-plated
Pin finishing:	gold-plated
Conductor material:	copper
Cable gauge:	30 AWG data line 28 AWG power line
Shielding:	triple
Length:	5 m
Colour:	black
Cable diameter:	6 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de