




AVAILABLE ACCESSORIES

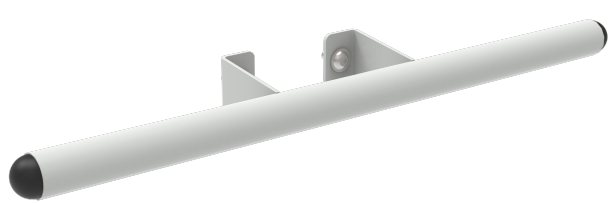

RT-HTT/ESD/45

Handle



RT-TT/ESD/90/62/T-2

ESD TECHNICAL TROLLEY
900 X 625



RT-TT/ESD/90/62/T-3

ESD TECHNICAL TROLLEY
900 X 625





• TECHNICAL SPECIFICATION

ESD TECHNICAL TROLLEY	RT-TT/ESD/90/62/T-2	RT-TT/ESD/90/62/T-3
Height adjustment – 1 shelf:	645–945 mm	
Width:	900 mm	
Depth:	625 mm	
Weight:	30 kg	33 kg
Load capacity: – 1 shelf:	50 kg	
Profil dimension:	50 x 30 x 1,5 mm	
Number of shelves:	2	3
Sheet thickness – shelf	1,50 mm	
Sheet thickness – construction	2,00 mm	
Internal shelf dimensions:	610 x 810 mm	
Color:	RAL 7035 (LIGHT GREY) RAL 9005 (BLACK)	
Type of castors:	ESD ø100mm	
Material:	CONSTRUCTION STEEL	
Resistance grounding:	10 ⁴ – 10 ⁸ Ohm	
ESD:	YES	
Compliance with standards:	ANSI/ESD S.20.20.2014, PN-EN 61340-5-1:2024, PN-EN ISO 9001:2015, PN-EN ISO 3834-2:2021, PN-EN 1090-1:2009+A1:2011	

