

Adapter DVI 24+1 male > DVI 24+5 female EDID Emulator

Description

This adapter by Delock emulates a monitor so that the signal source does not switch off the signal or change the resolution, even without a connected monitor. The adapter contains a standard set of EDID/DDC data, but it can also read and save the data of a connected monitor.



Item no. 63313

EAN: 4043619633135

Country of origin: China

Package: Retail Box


Technical details

- Connectors:
Input: 1 x DVI 24+1 male with screws
Output: 1 x DVI 24+5 female with nuts
- DVI-D (Single Link), VGA not wired
- Resolution up to 3840 x 2160 @ 60 Hz (depending on the system and the connected hardware)
- No external power supply needed
- 1 x LED indicator
- Plastic housing
- Colour: black
- Dimensions incl. connector (LxWxH): ca. 54.5 x 43.0 x 15.0 mm

Package content

- EDID emulator
- User manual

Images

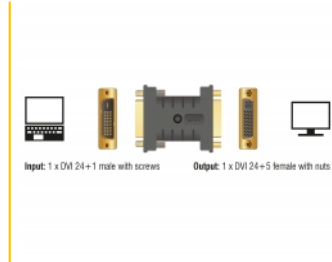

General

LED indicator:	1 x
----------------	-----

Interface

Output:	1 x DVI 24+5 female
Input:	1 x DVI 24+1 male

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 60 Hz
Voltage supply:	No external power supply needed

Physical characteristics

Housing material:	Plastic
Length:	54.5 mm
Width:	43.0 mm
Height:	15.0 mm
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de