



BETA 605DGT/2

Electronic torque wrench for torque up to 20 Nm



Certifications and Standards

CE  UNI EN ISO 6789

Features

Beta 605DGT/2, designed for tightening up to 20 Nm, offers immediate feedback, ensuring precision and reliability in every operation.

PRECISE AND SECURE

Our torque wrench offers a torque accuracy of $\pm 3\%$ right-hand and $\pm 4\%$ left-hand tightening. This guarantees high precision, allowing you to perform safe work by warning you when the desired torque is reached.

FUNCTIONAL

Possibility of peak or trace tightening in Nm, lbf.in., lbf.ft, kgcm.
Powered by 1 x 1.5V AAA battery (included)

POCKETABLE

A digital, compact and functional torque wrench in only 21 cm length.



TORQUE ATTAINMENT WARNING

Reaching the set torque is signalled visually by means of the LEDs and acoustically by a sound.



SQUARE 1/4"


1/4" square drive allows the use of both female sockets and screwdriver sockets with insert.



SIMPLE ADJUSTMENT

Buttons for easy setting of tightening torque, selecting the mode of use and the unit of measurement to be used.

Dimensions

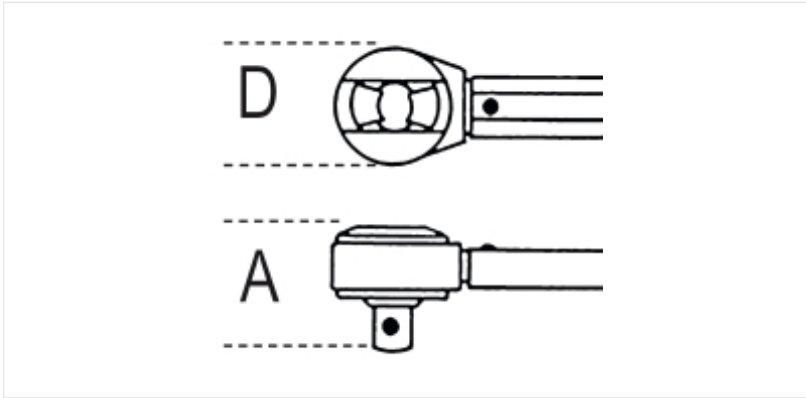

Certifications and Standards

  UNI EN ISO 6789

Coded items

	Art.	Nm	Kgcm	lbf.ft		D mm	A mm	L mm	 g	
006050302	605DGT/2	4÷20	0,4÷2	35÷177	1/4	20	20	210	175	0,01

