

DIONE




Wall-ceiling
montage
lamp
housing



DIONE

Lampshade version	Color		Catalogue no.
	Ring color	Base color	
lacteal	white	white	D.3140M
	black	black	D.3140CCM
	silver	white	D.3140SM
	gold	white	D.3140ZM
transparent	white	white	D.3140
	black	black	D.3140CC
	silver	white	D.3140S
	gold	white	D.3140Z

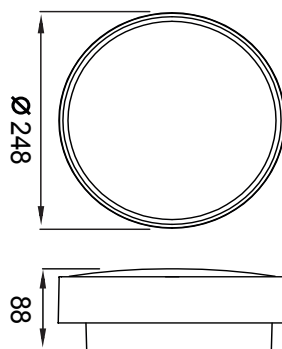

DIONE
with radar motion sensor

Lampshade version	Color		Catalogue no.
	Ring color	Base color	
lacteal	white	white	D.3140RM
	black	black	D.3140CCRM
	silver	white	D.3140SRM
	gold	white	D.3140ZRM
transparent	white	white	D.3140
	black	black	D.3140CCR
	silver	white	D.3140SR
	gold	white	D.3140ZR

DIONE

LED

DIONE LED

			Power - 9W		Power - 13W	
			white neutral	white cold	white neutral	white cold
Lampshade version	Ring color	Base color	Catalogue no.			
lacteal	white	white	D.3140M-BN-9W	D.3140M-BZ-9W	D.3140M-BN-13W	D.3140M-BZ-13W
	black	black	D.3140CCM-BN-9W	D.3140CCM-BZ-9W	D.3140CCM-BN-13W	D.3140CCM-BZ-13W
	silver	white	D.3140SM-BN-9W	D.3140SM-BZ-9W	D.3140SM-BN-13W	D.3140SM-BZ-13W
	gold	white	D.3140ZM-BN-9W	D.3140ZM-BZ-9W	D.3140ZM-BN-13W	D.3140ZM-BZ-13W

DIONE LED

with radar motion sensor

			Power - 9W		Power - 13W	
			white neutral	white cold	white neutral	white cold
Lampshade version	Ring color	Base color	Catalogue no.			
lacteal	white	white	D.3140RM-BN-9W	D.3140RM-BZ-9W	D.3140RM-BN-13W	D.3140RM-BZ-13W
	black	black	D.3140CCRM-BN-9W	D.3140CCRM-BZ-9W	D.3140CCRM-BN-13W	D.3140CCRM-BZ-13W
	silver	white	D.3140SRM-BN-9W	D.3140SRM-BZ-9W	D.3140SRM-BN-13W	D.3140SRM-BZ-13W
	gold	white	D.3140ZRM-BN-9W	D.3140ZRM-BZ-9W	D.3140ZRM-BN-13W	D.3140ZRM-BZ-13W



Power	White neutral 4000K	White cold 6500K
	Luminous flux	
9W	900 lm	850 lm
13W	1400 lm	1200 lm



PC

IP65

IK10

CRI
>80