

# SuperSpeed USB 5 Gbps Docking Station for 4 x SATA HDD / SSD with Clone Function

## Description

This HDD / SSD Docking Station in by Delock enables an external connection of up to **four 2.5" or 3.5" SATA HDDs / SSDs** through the USB interface, as well as the simple exchange of the drives by **Hot Swap**.

It is also possible to connect a single hard disk to the computer by using the **eSATA** connector.

### Four bays for HDD / SSD with clone function

Up to four HDDs or SSDs can be inserted and accessed simultaneously.

The **clone function** enables to copy the content of one HDD / SSD to one or more others without using a PC.

### USB Type-C™ connection and separate power supply

Due to the USB port and the included USB cable, the docking station can easily be connected to the computer. In addition, the power supply included in the delivery content ensures a supply for the storage devices used.



**Item no. 64063**

EAN: 4043619640638

Country of origin: China

Package: Retail Box

## Technical details

- Connectors:
  - 4 x SATA 22 pin receptacle
  - 1 x SuperSpeed USB 5 Gbps (USB 3.2 Gen 1) Type-B female
  - 1 x eSATA 7 pin plug
  - 1 x DC jack
- Chipset: JMicron JMS567, JMS391
- Function key:
  - 1 x Clone button
  - 1 x On / Off switch
- For 2.5" and 3.5" SATA HDD / SSD
- Suitable for all SATA HDDs / SSDs up to SATA 6 Gb/s
- Data transfer rate up to 3 Gb/s
- 5 x LED indicator
- LED indicator for power, access and copy status
- Bootable (eSATA)
- Dimensions (LxWxH): ca. 166 x 127 x 65 mm

- Hot Swap, Plug & Play

---

## Power supply specification

- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 2 A
- Output: 12 V / 6.5 A
- Ground outside, plus inside
- Dimensions:
  - inside:  $\varnothing$  ca. 2.1 mm
  - outside:  $\varnothing$  ca. 5.5 mm
  - length: ca. 10 mm

---

## System requirements

- Chrome OS
- Linux Kernel 3.17 or above
- Mac OS 10.14.2 or above
- Windows 7/7-64/8.1/8.1-64/10/10-64
- PC or laptop with a free USB Type-A port


---

## Package content

- Docking station
- 1 x cable USB 3.0 A male to USB 3.0 B male, length ca. 80 cm
- External power supply
- User manual

---

## Images

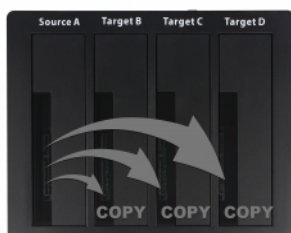

## General

Function:	Hot Swap Plug & Play bootable Clone Function
Suitable for data medium:	2.5" 3.5" SSD or HDD
Supported operating system:	Chrome OS Linux Kernel 3.17 or above Mac OS 10.14.2 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit

## Interface

External:	1 x DC 12 V power connector 1 x eSATA 6 Gb/s 7 pin plug 1 x USB 5 Gbps Type-B female
Internal:	4 x SATA 6 Gb/s 22 pin receptacle

## Technical characteristics

Data transfer rate:	5 Gbps
---------------------	--------

## Physical characteristics

Housing material:	Plastic
Length:	166 mm
Width:	127 mm
Height:	65 mm
Colour:	black

## Manufacturer information

---

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de