


TIE10 QuickMount

Direct-Mount Cable Tie Base Black & White

- DIRECT MOUNT
- FAST INSTALL
- GUN-READY
- UP TO 10 MM TIE
- UL 94 V-2
- ROHS COMPLIANT

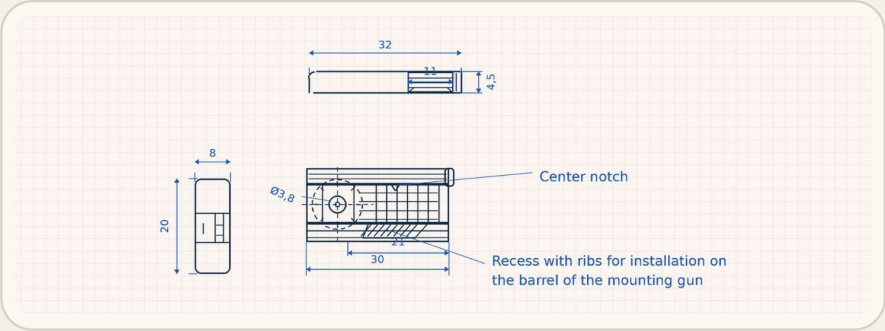

Technical specification

Materials	Black: Polyamide 6.6 + 1% carbon black; White: Polyamide 6.6
Colours	Black / White
Mounting	Direct installation or classic screw/dowel fixing
Self-adhesive	No
Tie width	Up to 10 mm
Mounting hole	Ø3.8 mm
Flammability	UL 94 V-2, self-extinguishing
Halogen-free	Yes
Working temperature	-25 °C to +60 °C
Installation temperature	-5 °C to +50 °C

Range & item codes

ITEM CODE	PRODUCT	COLOUR	L (MM)	W (MM)	H (MM)	PCS/PACK	PCS/CARTON
QM20X30B	Direct-Mount Cable Tie Base	Black	32	20	8	100	3,000
QM20X30W	Direct-Mount Cable Tie Base	White	32	20	8	100	3,000

Direct-mount cable tie base for open wiring, corrugated pipes and low-current installations.

↗ Gun-ready for fast direct installation.