


## Crocodile clips

### AGS 20

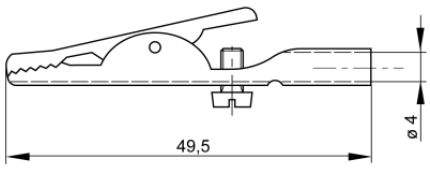

Product	AGS 20
description	Nickel-plated steel alligator clip. Clamping range up to a maximum bolt diameter 5 mm. 4 mm diameter socket connection, connection possible by terminal screw and solder connection.
operating instruction	BA420
Articlenummer	603006001
<b>drawing</b>	<b>Ni</b>
	
technical data	
connection	unsprung socket 4 mm, solder connection, screw terminal
rated voltage <sup>(1)</sup>	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(3)</sup>
rated current <sup>(1)</sup> (consider derating curve)	4 A
material socket	steel, nickel plated
temperature range acc. To IEC61010 <sup>(2)</sup>	-25 °C to +100 °C
clamping range	5 mm
standard	IEC 61010

4 mm system

<sup>(1)</sup> for normal environmental conditions -5°C to +40°C

<sup>(2)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(3)</sup> without rated measurement category, for other circuits that are not directly connected to mains

stand: 19.06.2019