

D-Type Module HDMI female to female 90° angled

Description

This module by Delock can be mounted e.g. in panels or cases with D-type openings for XLR jacks.

This makes it ideal for integrating digital equipment into professional audio systems.



Item no. 87811

EAN: 4043619878116

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
 - external: 1 x HDMI female
 - internal: 1 x HDMI female
- Material: zinc die cast
- Colour: black
- For D-type ports with 31 x 25 mm
- Panel cut-out (diameter): ca. 24 mm
- Two mounting holes for screw fastening
- Maximum resolution: 3840 x 2160 @ 60 Hz
- Dimensions (LxWxH): ca. 37 x 31 x 25 mm

Package content

- D-Type module

Images

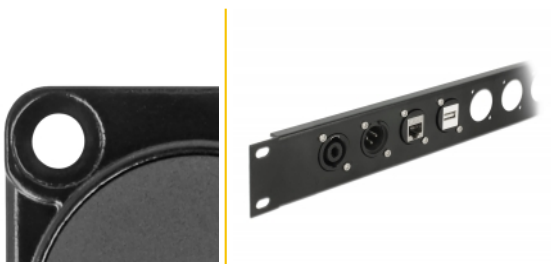

General

Mounting type:	D-Type
Style:	both sides identical

Interface

Connector 1:	1 x HDMI-A female
Connector 2:	1 x HDMI-A female

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 60 Hz
----------------------------	---------------------

Physical characteristics

Diameter:	24 mm
Length:	37 mm
Width:	31 mm
Height:	25 mm
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

