


mm [inch]

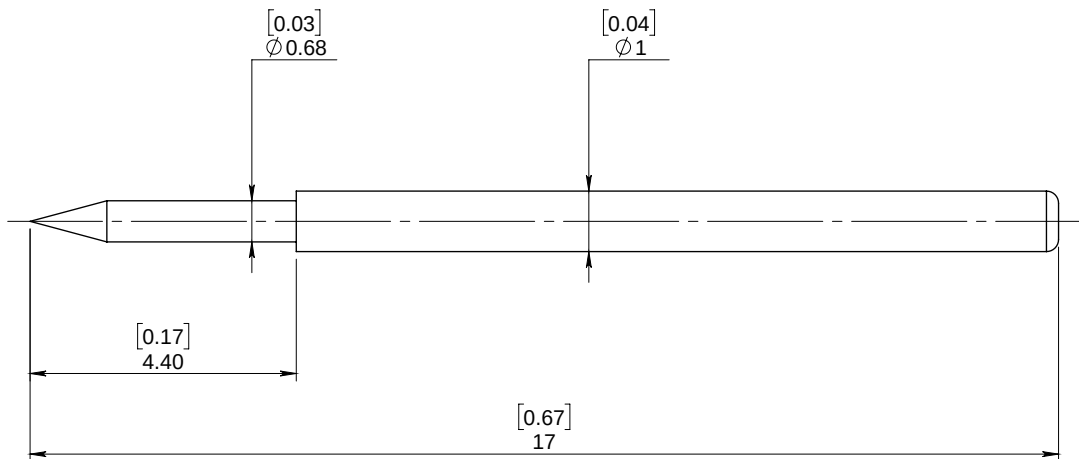

ST755 UB04 M

Minimum centers:	1.91 [.075]
Full travel:	3.00 [.118]
Working travel:	2.40 [.094]
Current rating:	3-4 A
Probe resistance:	< 100 mΩ
Operating temperature:	-30°C to +120°C
Plunger material:	BeCu / gold plated
Barrel material:	BeCu / gold plated
Spring material:	Spring steel / gold plated

Spring force at working stroke: 1.00 N [3.6 oz]

[illegible]