




A complete, versatile system of modular containers, perfectly integrable in the SYSTEM domestic range and able to meet the high protection installation requirements of the residential, commercial and industrial sectors. The 27 COMBI range is available both in the IP40 version and in watertight versions with IP55, IP65 and IP66 degree of protection, recommended for all outdoor applications which are subjected to extreme atmospheric conditions.

|                             |                               |                           |                     |
|-----------------------------|-------------------------------|---------------------------|---------------------|
| Description                 | 4 gang + 2 DIN modules        | Colour                    | Grey RAL 7035       |
| Door type                   | Rigid                         | Door colour               | Smoked Transparent  |
| No. knockout holes Ø23      | 10 on sides / 2 on the bottom | Type of knockout holes    | Removable with tool |
| IP degree                   | IP40                          | Insulation class          | II                  |
| Mechanical resistance       | IK07                          | Configuration             | Module 2 x 2        |
| Compartment pre-arrangement | 1                             | Type of enclosure         | GP                  |
| No. SYSTEM modules          | 4                             | No. DIN modules           | 2                   |
| Characteristics             | Halogen free                  | Lid screws                | Stainless steel     |
| Torque screws tightening    | 0.8 NM                        | Outer dim. LxHxD (mm)     | 132x132x95          |
| Dispersible power (W)       | 13                            | Rated voltage             | 400V ac             |
| Rated current (In)          | 32 A                          | Insulation voltage (Ui)   | 750 V               |
| Glow Wire Test              | 650 °C                        | Thermo-pressure with ball | 70 °C               |
| Standard                    | EN 60670-1 - EN 60670-24      | Installation temperature  | -25 +60 °C          |
| Electrocod                  | 0212                          |                           |                     |

#### BEHAVIOUR WITH CHEMICAL AND ATMOSPHERIC AGENTS

| Saline solution | Acids              |           | Bases        |           | Solvents           |               |               |               | Mineral oil        | UV rays   |
|-----------------|--------------------|-----------|--------------|-----------|--------------------|---------------|---------------|---------------|--------------------|-----------|
|                 | Concentrated       | Diluted   | Concentrated | Diluted   | Hexane             | Benzol        | Acetone       | Alcohol       |                    |           |
| Resistant       | Limited resistance | Resistant | Resistant    | Resistant | Limited resistance | Not resistant | Not resistant | Not resistant | Limited resistance | Resistant |

#### DIMENSIONAL

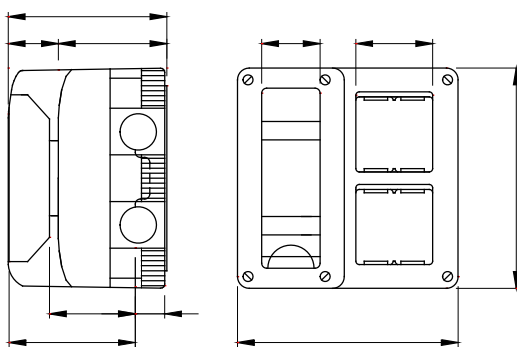

#### TECHNICAL SYMBOLOGY



IP

IP40



II

IK

IK07



Halogen free

GWT

650 °C



70 °C

#### STANDARDS/APPROVALS



GEWISS S.p.A. Via A. Volta, 1  
24069 Cenate Sotto - Bergamo - Italy  
tel. +39 035 94 61 11 fax +39 035 94 69 09  
Company subject to the management and  
coordination of Polifin S.p.A.

www.gewiss.com  
sat@gewiss.com  
Last update 23/01/2026

Data, measures, designs and pictures are shown  
only as informative purposes,  
and could be changed without previous notice