

Adapter USB 2.0 Type-A > 2 x Serial DB9 RS-232

Description

The USB 2.0 to serial adapter by Delock enables you to connect 2 serial devices to a free USB port of your PC or laptop.



Item no. 61886

EAN: 4043619618866

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
1 x USB 2.0 Type-A male
2 x serial RS-232 DB9 male
- Chipset: FTDI
- Serial male port with screws
- Data transfer rate up to 460.8 Kbps
- Supports remote wake-up and power management
- Cable length: ca. 1.4 m



System requirements

- Windows 7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port

Package content

- USB 2.0 to 2 x serial adapter
- Driver CD
- User manual

Images

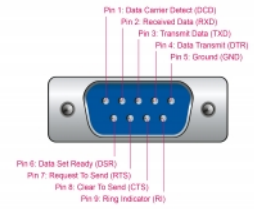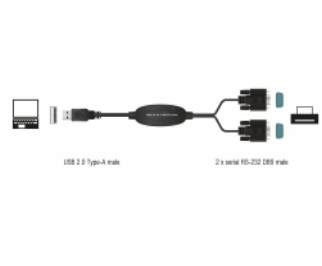

General

| | |
|-----------------------------|--|
| Function: | Plug & Play |
| Specification: | RS-232 (EIA / TIA) USB 2.0 |
| Supported operating system: | Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8 32-bit Windows 8 64-bit Windows 8.1 32-Bit Windows 8.1 64-Bit |
| LED indicator: | Power |

Interface

| | |
|--------------|----------------------------|
| Connector 1: | 1 x USB 2.0 Type-A male |
| Connector 2: | 2 x serial RS-232 DB9 plug |

Technical characteristics

| | |
|---------------------|---|
| Chipset: | FTDI FT2232HL |
| Data transfer rate: | 460.8 Kbps |
| Data transmission: | asynchronous full duplex |
| Voltage supply: | USB Bus powered (no additional power supply required) |

Physical characteristics

| | |
|--------------------------------|-----------|
| Housing colour: | black |
| Housing material: | Plastic |
| Cable colour: | black |
| Cable length incl. connectors: | 1.4 m |
| Screw type: | #4-40 UNC |

Manufacturer information

| | |
|-------------|-------------------|
| Street | Beeskowdamm 13/15 |
| Postal code | 14167 |
| City | Berlin |
| Country | Deutschland |
| E-Mail | info@delock.de |
| Website | www.delock.de |