




## Qoltec Self-locking cable tie | 3.6\*100 mm | Nylon UV | Black

Product code: 52243

High-quality self-locking cable tie by Qoltec will find use virtually anywhere thanks to its functionality. Very easy installation and high mechanical strength guarantee satisfaction of use.

Width: 3.6 mm  
Length: 100 mm  
Quantity: 100

### What is the Self-locking cable tie ?

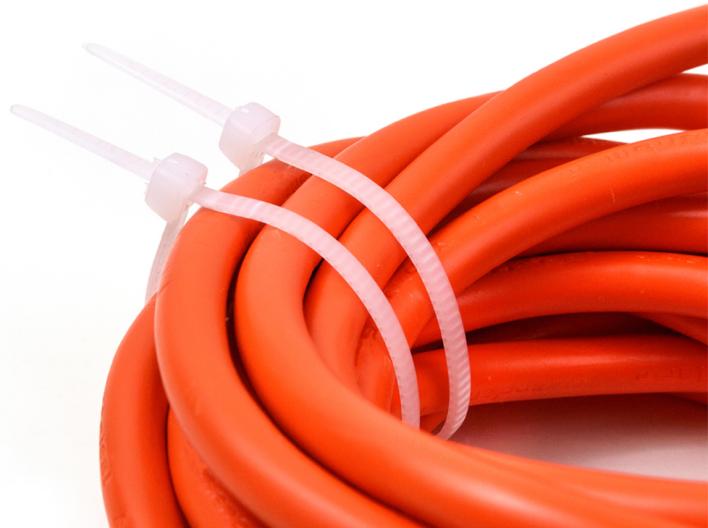

Qoltec brand Self-locking cable tie are made of flexible and durable nylon. They are designed to connect different types of elements together, such as cable organization. Thanks to their versatility, they are used virtually everywhere. Among other things, they can be found in the household, telecommunications, automotive workshops, gardening, electrical installations, warehouses and more.

## How to use Self-locking cable tie ?



The use Self locking cable ties is very quick and easy. Just fit the clamp to the objects to be joined, then put the end of the clamp through the hole and clamp. The clamp is very flexible and elastic, which allows you to easily adjust the clamp. In addition, the evenly spaced teeth on the tip will make it easier to accurately fit the parts to be joined.

## Choose high quality

The Qoltec brand Self locking cable tie is a top quality, reusable, tear-resistant product. The Self locking cable ties retain their properties in the temperature range from -35 C to +85 C. They feature UV resistance and chemical resistance.

## Confidence backed by warranty

Do you care about the high quality of the product you buy? Our solutions will meet your expectations. Self locking cable tie are covered by a 24-month warranty valid from the date of purchase.

## Technical data

Producer	Qoltec
Material	Nylon 66
Quantity	100 pcs
Colour	Black
Operating temperature	-35°C ~ +85°C
Resistance grade	UL 94 kl. V2
Package depth / length	180 mm
Package width	106 mm
Package height	10 mm
Length	100 mm
dimensions	7.2*350 mm
Additional information	<ul style="list-style-type: none"><li>- easy to install</li><li>- UV resistance</li><li>- high thermal strength</li><li>- high mechanical strength</li><li>- resistant to acids</li><li>- resistant to high temperature</li><li>- resistant to erosion</li></ul>
Net weight	0,038 kg
Gross weight	0,039 kg
Warranty	24 month
EAN code	5901878522432