

Technical data sheet

90° bend 60

Item no. 6225044



St	Steel
FS	Strip galvanised


90° bend, horizontal, with welded rung for all cable ladder types of 60 mm side height.

Additional product text, instruction	Connectors should be ordered separately and in the appropriate quantity.
--------------------------------------	--

Master data

Item no.	6225044
Type	LB 90 630 R3 FS
Description 1	90° bend
Description 2	for cable ladder
Dimension	60x300
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	1,00 Piece
Weight	318,30 kg/100 pc.

Technical data

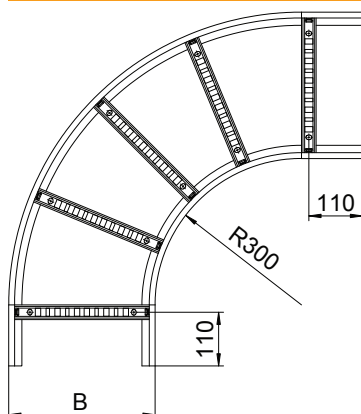

Width	300,00 mm
Side height	60,00 mm
Dimension B	300,00 mm
Dimension R	300,00 mm
Bend (angle)	90°
Connector version	Without connectors
Rung version	Profile perforated
Side rail version	Flat profile
Suitable for maintaining electrical function	☐
Rail thickness	1,50 mm
Change of direction	Horizontal
Rustproof steel, pickled	☐
Hinged	☐
Side perforation	☐
Wide-span version	☐