


	~DIN 933/931			PA 6.6
---	--------------	--	--	--------

Norme abrogée

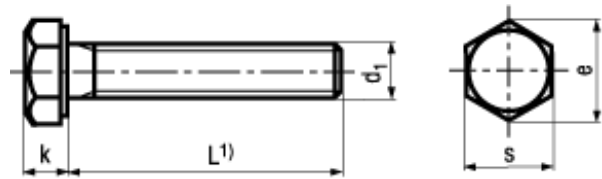

1) Entièrement ou partiellement filetée selon choix du fournisseur

BN 80

Vis à tête hexagonale

Polyamide PA 6.6

nature

- ~UNI 5739/5737
- ~CSN 021101/021103

Article#	d ₁	e	s	k	L
8118035	M3	6,01	5,5	2	12
8042691					16
8042705					20
1399608	M4	7,66	7	2,8	6
1399616					8
1399624					10
1399632					12
1399640					16
1399659					20
1399667					25
1399675					30
1399683					40
1399691	M5	8,79	8	3,5	6
1399705					8
1399713					10
1399721					12
1399748					16
1399756					20
1399764					25
1399772					30
1399780					35
1399799					40
1399802					50
1399829	M6	11,05	10	4	10
1399837					12
1399845					16

Article#	d ₁	e	s	k	L
1399853	M6	11,05	10	4	20
1399861					25
1399888					30
1399896					35
1399918					40
1399926					45
1399934					50
1399942					60
1399950					70
1399969					(75)
1399977	M8	14,38	13	5,3	10
1399985					16
1399993					20
1400002					25
1400010					30
1400029					35
1400037					40
1400045					50
1400053					60
1400061					70
1400088					80
1400096	M10	17,77	17	6,4	20
1400118					25
1400126					30
1400134					35
1400142					40
1400150					45
1400169					50
1400177					55
1400185					60
1400193					70
1400207					80
1400215	M12	20,03	19	7,5	20
1400223					25
1400231					30
1400258					35
1400266					40
1400274					45
1400282					50
1400312					70
1400320					80

Article#	d ₁	e	s	k	L
1400339	M16	26,75	24	10	50
1400347					55
1400355					60
1400363					70
1400371					90
1400398					110