

Cable Optical Fibre LC > LC Multi-mode OM5 Uniboot 3 m

Description

This fibre optical cable by Delock can be used to connect different networking devices, e.g. a NIC with an SFP module to a switch or a media converter. Both conductors share one sheath and one boot, making the cable very space efficient. The extractor lever makes it easy to unplug from high density panels.



3 m

Item no. 85690

EAN: 4043619856909

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x LC Duplex >
 - 1 x LC Duplex
- Multi-mode OM5 cable
- Fibre: 50/125 µm
- Zirconia ceramic ferrule with protection cap
- Uniboot connector
- Extractor lever
- Polarity changeable
- Shared outer sheath
- Cable diameter: ca. 3 mm
- In 50 Ohm (not shielded)
- Colour: limegreen
- Cable length: ca. 3 m


System requirements

- One free LC duplex port

Package content

- Optical Fibre Cable

Images

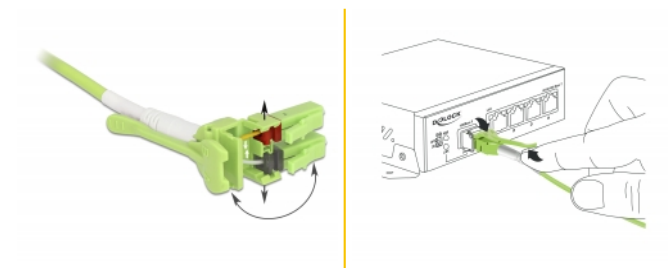

General

Specification:	OM5
Style:	both sides identical

Interface

Connector 1:	1 x LC Duplex
Connector 2:	1 x LC Duplex

Physical characteristics

Cable colour:	lime green
Length:	3 m
Cable diameter:	3 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

