

Flat suction cup (round)

SPF 40 ED-65 G1/4-AG

Part no.:10.01.01.13246

<https://www.schmalz.com/10.01.01.13246>

Homepage > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Packaging > Flat Suction
Cups SPF > SPF 40 ED-65 G1/4-AG

Flat suction cup (round) for dynamic handling of cardboard and rigid packaging




Size: 40

Suction cup material: Elastodur

Material hardness: 65 °Sh

Thread G1: G1/4"-M

Design Data

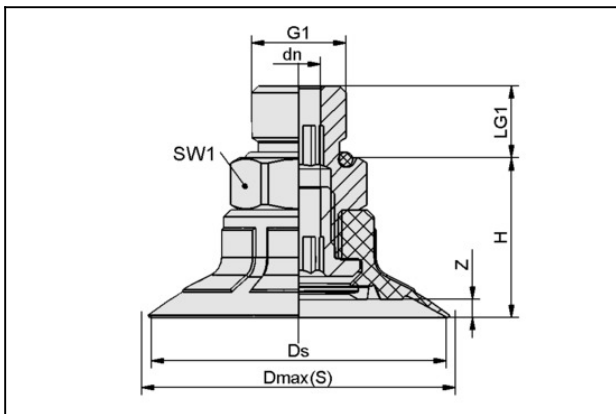

Attribute	Value
dn	6.1 mm
Dmax(S)	43.7 mm
Ds	41.4 mm
G1	G1/4"-AG
H	22.2 mm
LG1	10 mm
SW1	17 mm
Z (Stroke)	2.5 mm

Technical Data

Flat suction cup (round)

SPF 40 ED-65 G1/4-AG

Part no.:10.01.01.13246

<https://www.schmalz.com/10.01.01.13246>



Attribute	Value
Suction force (-600mbar)	49.5 N
Pull-off force	62.5 N
Lateral force	25 N
Volume	5.091 cm ³
Curve radius (min) (convex)	70 mm
Hose diameter (empf.) d	6 mm
Size	40
Number of folds	0
Suction cup material	Elastodur
Material hardness [Shore A]	65 Shore A
Weight	18.8 g
Product family	SPF

Note: Suction force: The specified suction forces are theoretical values at a vacuum of -0.6 bar and with a smooth, dry workpiece surface - they do not include a safety factor Hose diameter: The recommended hose diameter refers to a hose length of approx. 2 m

Spare Parts



SC 050 G1/4-AG

Part no.10.01.06.02487

Connection element for suction cup "SchmalzConnector"

Connection geometry: 050

Vacuum connection: G1/4"-M

Overall length: 26.5 mm

Fitting length: 7.2 mm


Nominal diameter dn: 6.1 mm

Flat suction cup (round)

SPF 40 ED-65 G1/4-AG

Part no.:10.01.01.13246

<https://www.schmalz.com/10.01.01.13246>

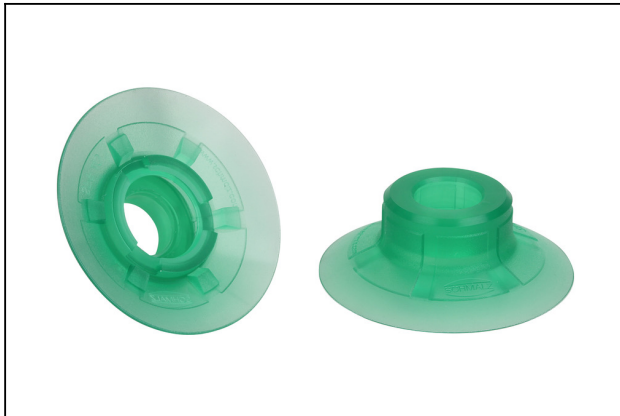

SPF 40 ED-65 SC050

Part no.10.01.01.12373

Flat suction cup (round) for dynamic handling of cardboard and rigid packaging

Size: 40

Suction cup material: Elastodur

Material hardness: 65 °Sh

Accessories



SIEB 17.5x0.8 MS-A2 280 0.28/0.16

Part no.10.07.01.00308

Screen

External diameter D: 17.5 mm

Length L: 0.8 mm

Material: Brass / Stainless steel

Filter pore size: 280 µm

Mesh: 0.28 mm

Wire size: 0.16 mm



SU 40

Part no.10.01.01.12856

Cover for suction cup

Size: 40

Clamping range: 35.0 ... 45.0 mm

Temperature resistance: 80 °C