



# HAHN - Elektrobau GmbH & Co. KG

Bellersheimerstraße 45  
35410 Hungen  
Germany

phone: +49 (0) 6402/808-0  
fax: +49 (0) 6402/808-60  
email: info@hahn-trafo.de

## Data sheet: BV 201 0145


|                        |                |         |
|------------------------|----------------|---------|
| Size 1 a: height 15 mm | Type BV 201... | 0,35 VA |
|------------------------|----------------|---------|

shipping unit per box: **50 pcs.** / temperature class: **ta 70/B** / weight: **approx. 25g**

|                                                               |
|---------------------------------------------------------------|
| - absolutely short circuit proof                              |
| - <b>excellent function at thermal changes, vacuum casted</b> |
| - maximum safety and long-term durability                     |
| - <b>with VDE-, ENEC 10-, UL-, and CSA certificates</b>       |
| - minimum size, maximum capacity                              |
| - <b>self-extinguishing cast housing and sealing material</b> |
| - individually tested with certificate                        |

| Article no. BV | Output ta 70°C/B | prim.V | Connecting pins | Operating point<br>sec. $\pm 5\%$ | Connecting pins | No-load voltage<br>V $\pm 5\%$ |
|----------------|------------------|--------|-----------------|-----------------------------------|-----------------|--------------------------------|
| BV 201 0145    | 0,35             | 230    | 1-4             | 12 V 29 mA                        | 6-7             | 20,8                           |

## Certificates

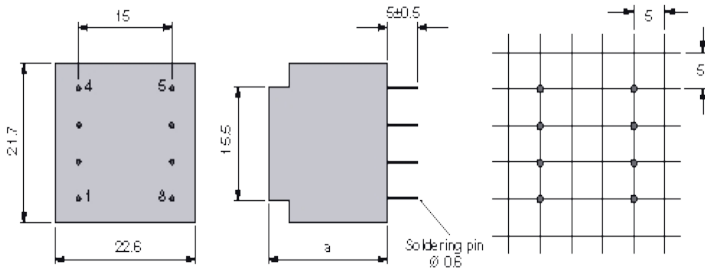

Dimensions with no indication of tolerances:  $\pm 0.3$  mm