


# Cable Optical Fibre LC-APC to SC-APC Simplex Singlemode OS2 10 m

## Description

This fibre optic cable by Delock can be used to connect various network devices, e.g. an FTTH house interconnection point with a fibre optic modem.

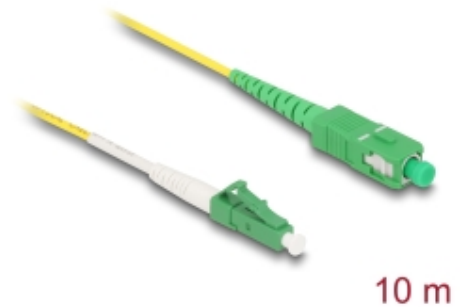

**Item no. 83876**

EAN: 4043619838769

Country of origin: China

Package: Zip poly bag

## Technical details

- Connectors:  
1 x LC-APC Simplex  
1 x SC-APC Simplex
- APC 8°
- Ceramic ferrule with dust protection
- Singlemode OS2 cable G657.A2
- Fibre: 9/125 µm
- Return loss: 60 dB
- Smallest bending radius: 7.5 mm
- Cable diameter: ca. 2.0 mm
- LSOH (halogen-free)
- Operating temperature: -20 °C ~ 70 °C
- Colour: yellow
- Cable length: ca. 10 m

## Package content

- Optical fiber cable

---

## Images



## General

|                |     |
|----------------|-----|
| Specification: | OS2 |
|----------------|-----|

## Interface

|              |                     |
|--------------|---------------------|
| Connector 1: | 1 x LC Simplex male |
| Connector 2: | 1 x SC Simplex male |

## Technical characteristics

|                        |                |
|------------------------|----------------|
| Operating temperature: | -20 °C ~ 70 °C |
|------------------------|----------------|

## Physical characteristics

|                                |                     |
|--------------------------------|---------------------|
| Cable colour:                  | yellow              |
| Cable length incl. connectors: | 10 m                |
| Smallest bending radius:       | 7.5 mm              |
| Cable jacket material:         | LS0H (halogen-free) |

## Manufacturer information

|             |                   |
|-------------|-------------------|
| Street      | Beeskowdamm 13/15 |
| Postal code | 14167             |
| City        | Berlin            |
| Country     | Deutschland       |
| E-Mail      | info@delock.de    |
| Website     | www.delock.de     |

