


DIN 3113 - UNI ISO 7738

- Compact heads
- High resistance to corrosion
- Avoids improper rust
- Outstanding mechanical characteristics
- AISI 420 stainless steel

	Art.	M mm	M1 mm	L mm	H mm	Ø mm	S mm	S1 mm	α °	Wt g
000420306	42INOX 6	6	6	95	15,2	10,4	5,2	3,4	15	12
000420307	42INOX 7	7	7	105	17,1	11,1	5,7	3,6	15	16
000420308	42INOX 8	8	8	116	19	12,6	6,2	3,9	15	23
000420309	42INOX 9	9	9	127	20,9	14,1	6,7	4,2	15	27
000420310	42INOX 10	10	10	137	22,8	15,4	7,1	4,5	15	35
000420311	42INOX 11	11	11	148	24,8	16,8	7,5	4,8	15	44
000420312	42INOX 12	12	12	158	26,9	18,2	7,9	5,1	15	54
000420313	42INOX 13	13	13	169	28,8	19,6	8,4	5,4	15	66
000420314	42INOX 14	14	14	180	30,8	21	8,8	5,7	15	80
000420315	42INOX 15	15	15	190	32,7	22,4	9,2	6,0	15	90
000420316	42INOX 16	16	16	201	34,6	23,8	9,7	6,3	15	105
000420317	42INOX 17	17	17	212	36,6	25,2	10,2	6,7	15	120
000420318	42INOX 18	18	18	222	38,5	26,7	10,8	7,0	15	140
000420319	42INOX 19	19	19	233	40,5	28	11,4	7,3	15	160
000420321	42INOX 21	21	21	254	44,5	30,7	12,4	7,9	15	205
000420322	42INOX 22	22	22	264	46,4	32,2	12,8	8,1	15	225
000420324	42INOX 24	24	24	285	50,3	34,9	13,5	8,5	15	290
000420327	42INOX 27	27	27	290	53	42	12	9,0	15	430
000420330	42INOX 30	30	30	320	59	46	13	10,0	15	530
000420332	42INOX 32	32	32	340	63	49	14	11,0	15	635
000420336	42INOX 36	36	36	360	70	55	20	16,0	15	960
000420338	42INOX 38	38	38	430	85	64	21	16,0	15	1300
000420341	42INOX 41	41	41	430	85	64	21	16,0	15	1300
000420343	42INOX 46	46	46	480	90	70	21	16,0	15	1760
000420345	42INOX 50	50	50	520	98	77	23	17,0	15	2000
000420347	42INOX 55	55	55	560	108	83	23	18,0	15	2500
000420350	42INOX 60	60	60	595	115	89	26	20,0	15	2900

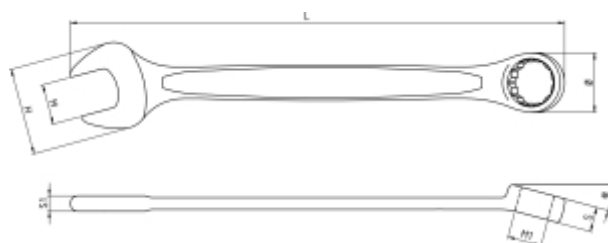

Scan the QR Code to access the web tab

Specs, media and documentation in one click.

