

 
DUAL MONITOR SPRING DESK MOUNT 17" – 32"



2 × 17" – 32"
SCREEN SIZE



UP TO 2 × 9 KG
WEIGHT
CAPACITY



75 × 75,
100 × 100
VESA COMPATIBLE



DUAL
ERGONOMIC
SCREEN
SETTING




CABLE
MANAGEMENT



SPRING
MECHANISM

EN DUAL MONITOR SPRING DESK MOUNT 17" – 32"

Screen size compatibility:	17" – 32" (per screen)
Max weight capacity:	Up to 9 kg (per screen)
VESA compatibility:	75 × 75, 100 × 100
Tilt range:	+ 90° ~ - 90°
Swivel range:	+ 90° ~ - 90°
Screen rotation:	+ 180° ~ - 180°
Arms full extension:	506 mm
Material:	Steel, plastic
Surface finish:	Powder coating
Dimensions of product:	948 × 109 × 564 mm
Weight of product:	3.98 kg
Color:	Black
Installation:	Clamp, grommet
Desktop thickness for clamp:	10 – 80 mm
Desktop thickness for cables grommet:	10 – 48 mm
Package content:	Monitor desk mount, mounting elements, user manual

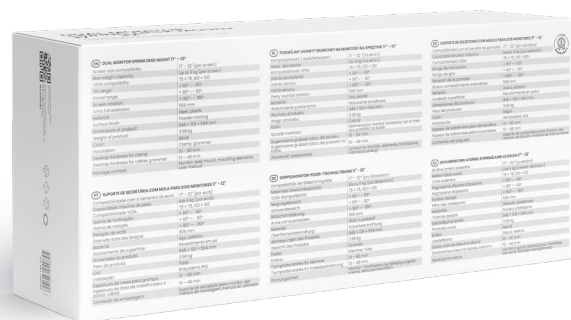

The Savio UM-04 dual monitor desk mount with a gas spring mechanism combines modern design, full adjustability, and maximum comfort. Designed for two monitors ranging from 17" to 32" and weighing up to 9 kg each, it offers exceptional smoothness of movement thanks to the integrated spring mechanism. You can easily and effortlessly adjust your screens to the exact position you need – without applying force.

A wide range of adjustments – tilt (+90°/-90°), swivel (+90°/-90°), and screen rotation (+180°/-180°) – allows for ergonomic and flexible workspace organization. The extended arm reach of up to 506 mm makes this mount perfect not only for office work but also for gaming, video editing, or design tasks.

Its solid steel and plastic construction, finished with a durable powder coating, ensures both stability and aesthetics. The mount is installed non-invasively using either a desk clamp (for desktops 10–80 mm thick) or a grommet mount (for desktops 10–48 mm thick). Compatibility with VESA 75×75 and 100×100 standards ensures wide monitor support.