

USB 2.0 Cable USB Type-C™ male to EASY USB Type-A female 3 m

Description

This USB cable by Delock enables the connection between devices with a USB Type-A port, e.g. USB sticks, a mouse or an external HDD, and a PC or laptop with a USB Type-C™ port.

User-friendly reversible EASY USB female connector

The EASY USB socket is twist-proof and can be used on both sides, so there is no need to pay attention to the correct top or bottom side when inserting a plug.



Item no. 81538

EAN: 4043619815388

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
 - 1 x USB 2.0 Type-C™ male
 - 1 x USB 2.0 Type-A reversible female
- USB Type-A female usable in both directions
- Host = USB Type-C™; Device = USB Type-A
- Cable gauge:
 - 28 AWG data line
 - 24 AWG power line
- Resistor: 5.1 kΩ
- Output current: up to 3 A
- Cable diameter: ca. 4.5 mm
- Gold-plated connector
- Cable double shielded
- Data transfer rate up to 480 Mbps
- Colour: black
- Length incl. connectors: ca. 3 m

Package content


 
- USB cable

Images



EASY-USB

PCB with both
sided contacts

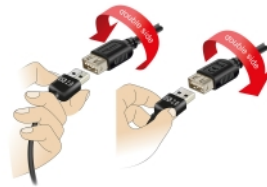

General

Style:	EASY-USB
--------	----------

Interface

Connector 1:	1 x USB 2.0 Type-C™ male
Connector 2:	1 x EASY-USB 2.0 Type-A female

Technical characteristics

Data transfer rate:	480 Mbps
---------------------	----------

Physical characteristics

Pin finishing:	gold-plated
Cable gauge:	28 AWG data line 24 AWG power line
Shielding:	double
Length:	3 m
Colour:	black
Cable diameter:	4.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de