


DIGITUS DisplayPort Adapter / Converter

AK-340406-001-W
EAN 4016032289579

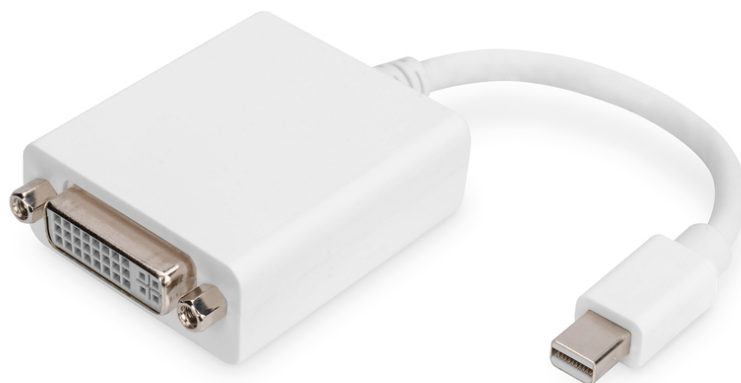

DisplayPort adapter cable, mini DP - DVI (24+5) M/F, 0.15m, DP 1.1a compatible, wh

This digital HD adapter / converter suits ideal to connect a MacBook®, MacBook Air®, MacBook Pro®, iMac®, Mac mini® and Mac Pro® to a DVI monitor, beamer, LCD/TFT Monitor, LED or plasma TV with a DVI cable, for example.

Ensures a lower burden of the interface.

- Support up to 1080p with 60Hz
- Supported transmission modes: RBR, HBR, HBR2
- Maximal bandwidth: 10,8 Gbps
- HBR-Version/transfer mode: HBR1 (2,70 Gbit/s per lane)
- HDCP-Version: HDCP 1.3
- Assortment: DisplayPort Cables
- AWG: 32

- Color cable: white
- Color connector: white
- Connector 1: Mini DP, plug
- Connector 2: DVI-I, (24+5), jack
- Connector surface: nickel-plated
- DisplayPort standard: DisplayPort 1.1a
- Ferrite filter: none
- HDTV Standard: Full HD
- Hoods: molded
- Interlock: none
- Packaging: Polybag
- Wire material: CU
- Length: 0.15 m
- AOC - Active Optical Cable: no
- Shielding: Double shielding

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	200	8.40	38.10	30.20	31.10	35,784.30
Packaging Unit Inside	10	0.42	40.60	40.60	8.10	13,351.70
Packaging Unit Single	1	0.04	20.00	15.00	1.62	486.00
Net single without Packaging	1	0.04	20.00	15.00	1.62	486.00

More images:

