

RJ45 Coupler LSA to LSA with strain relief Cat.6A toolfree

Description

This coupler by Delock can be used to connect, extend or repair twisted pair cables. The sturdy metal housing ensures a secure and long-lasting connection.

With strain reliefs

The strain reliefs protect the cables from damage or abrasion and prevent heavy tensile strain.



Item no. 87064

EAN: 4043619870646

Country of origin: China

Package: Zip poly bag


Technical details

- Connectors:
 - 1 x LSA (toolfree)
 - 1 x LSA (toolfree)
- Cat.6A specification
- TIA-568B pinout
- For solid or stranded wire (26 - 22 AWG)
- For cable diameter from 6.0 - 9.5 mm
- Material: zinc diecast
- Dimensions (LxWxH): ca. 107.0 x 15.9 x 15.4 mm

Package content

- RJ45 coupler
- 2 x cable manager
- 2 x strain relief
- 2 x cable tie

Images

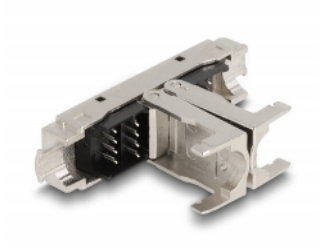

General

Specification:	Cat. 6A
----------------	---------

Interface

Connector 1:	1 x LSA (toolfree)
Connector 2:	1 x LSA (toolfree)

Physical characteristics

Cable gauge:	26 - 22 AWG
Material:	zinc die cast
Length:	107 mm
Width:	15.9 mm
Height:	15.4 mm
Cable diameter:	6,0 - 9.5 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

