

TIE10 FlexiPipe

Corrugated Pipe Clip 16–32 mm

CORRUGATED PIPE


PE MATERIAL

3 COLOURS

DIRECT FIXING

16–32 MM

ROHS COMPLIANT

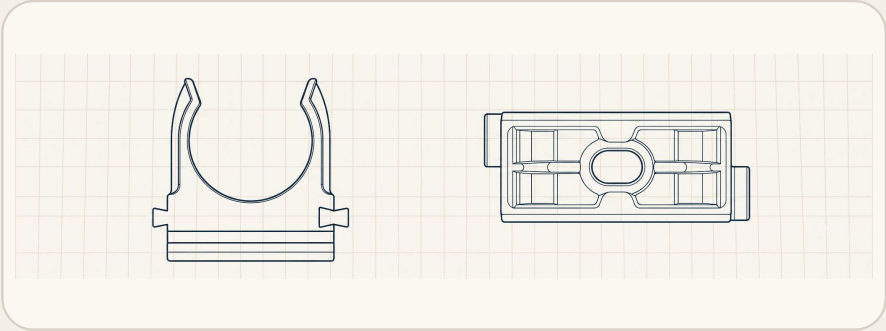

Technical specification

Material	Polyethylene PE
Colours	Black / Grey / White
Available sizes	16 / 20 / 25 / 32 mm
Working temperature	-20 °C to +100 °C
Installation temperature	-10 °C to +60 °C
Resistant to	Aqueous solutions of salts, acids and alkalis

Range & item codes

ITEM CODE	PRODUCT	COLOUR	PCS/PACK	PCS/CARTON
TTC16B	Corrugated Pipe Clip 16 mm	Black	100	2,500
TTC16G	Corrugated Pipe Clip 16 mm	Grey	100	2,500
TTC16W	Corrugated Pipe Clip 16 mm	White	100	2,500
TTC20B	Corrugated Pipe Clip 20 mm	Black	50	1,750
TTC20G	Corrugated Pipe Clip 20 mm	Grey	50	1,750
TTC20W	Corrugated Pipe Clip 20 mm	White	50	1,750
TTC25B	Corrugated Pipe Clip 25 mm	Black	50	1,250
TTC25G	Corrugated Pipe Clip 25 mm	Grey	50	1,250
TTC25W	Corrugated Pipe Clip 25 mm	White	50	1,250
TTC32B	Corrugated Pipe Clip 32 mm	Black	50	750
TTC32G	Corrugated Pipe Clip 32 mm	Grey	50	750
TTC32W	Corrugated Pipe Clip 32 mm	White	50	750

One datasheet for all FlexiPipe sizes and colour variants.