




UQS-COB-8W-Y-24V-5m

Professional Led Strip, 8W/m

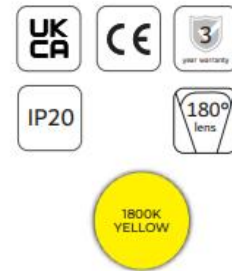

■ Features:

- Uniform lighting
- Uniform light line
high luminous intensity
- 3 years warranty

TECHNICAL DETAILS

MODEL	UQS-COB-8W-Y-24V-5m
Supply voltage	24V $\pm$ 0.5Vdc
Power	8W/m
Power per reel	40W
Color temperature	YELLOW
Beam angle	180°
Luminous flux per meter	720 lm 1800K
Maximum length for one sided supply	5m
IP protection degree	IP20
Working temperature	-25°C ÷ 50°C
Storage temperature	-30°C ÷ 80°C
LED QTY	320 LEDs/m
Width PCB	8 mm
Cut section	50 mm
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 360 mm: V+: red: V-:black.
Dimensions (L x W x H)	5004 x 12 x 2.8 mm
Packing	5m / reel (bag)

MECHANICAL SPECIFICATION:

