




Thermowell for temperature sensors

THERMOWELL, D6/1,5"CLAMP/L=100

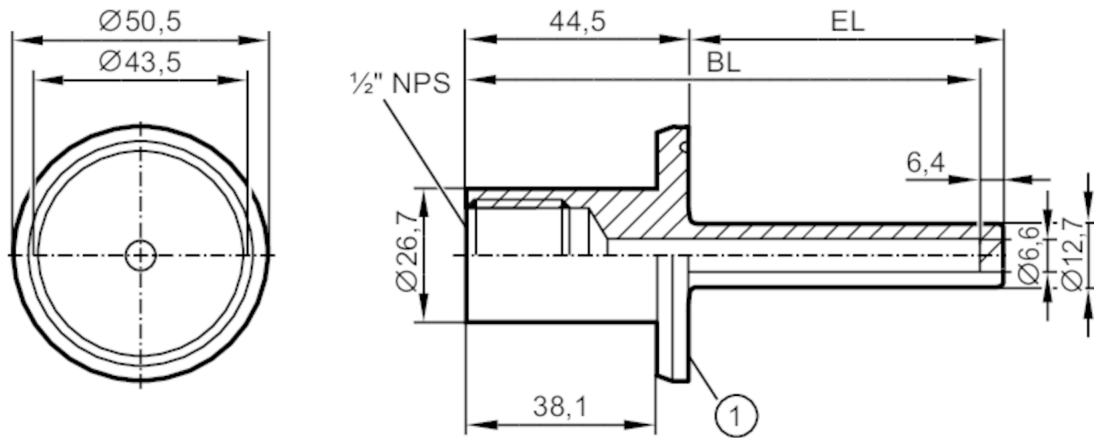

1 1.5" Clamp (ISO 2852)



EC 1935/2004 EHEDG Certified



Application

Design	for temperature sensors EL = 100 mm	
Pressure rating [bar]		25
Pressure rating [MPa]		2.5

Mechanical data

Weight [g]		241
Materials		stainless steel (316L/1.4404)
Sensor connection		1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT
Process connection		Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)
Surface characteristics Ra/Rz of the wetted parts		≤ 0.6 / -
Installation length EL [mm]		64
Bore length BL [mm]		101.6

Remarks

Pack quantity		1 pcs.
---------------	--	--------